


AK-4A-F10

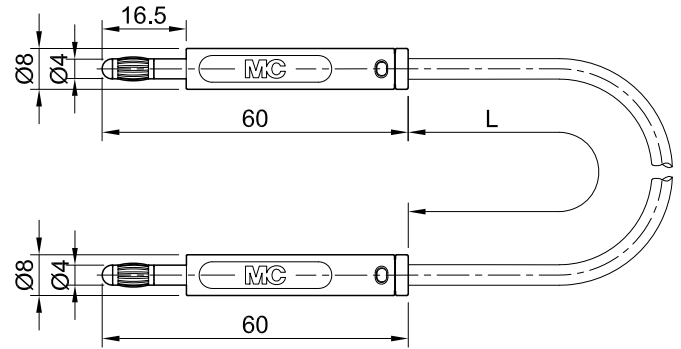

Item number 64.1071- *

Highly flexible with in-line Ø 4 mm MULTILAM plugs on both ends.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 V, 19 A / 60 V, 19 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	21 22
Optional color(s)	20 23 24 25 26 27 28 29
Lead lengths <input type="text"/>	050; 100; 200 cm
Lead insulation	PVC
Lead cross section	1,0 mm ²
Test accessory acc. to	IEC EN 61010-031
User-Information	I 096