


APK-4

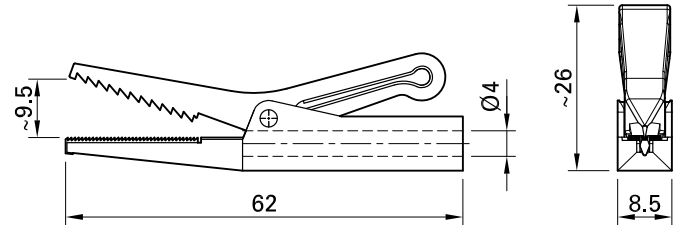

Item number 64.9209-*

Insulated, with \varnothing 4 mm rigid socket. Brass. Sharp toothed, pointed jaws. The upper jaw is insulated.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 V, 10 A / 60 V, 10 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22 23 24 25 26
Opening width	9.5 mm
Test accessory acc. to	IEC EN 61010-031