


SLB2-R

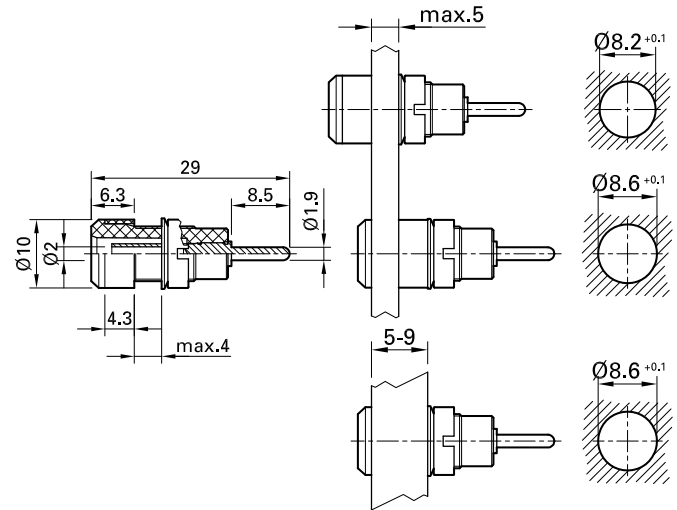

Item number 65.9194-*

Insulated, rigid, accepting spring-loaded Ø 2 mm plugs with rigid insulating sleeve. The socket is surface-mounted or assembled flush into pre-drilled panels of plastic, metal, etc. Round connecting pin Ø 1.9 mm.

Technical data	
Diameter of plug system	2 mm
Rated Values	1000 V, CAT II, 10 A / 600 V, CAT III, 10 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	21 22 23 24 25 29
Test accessory acc. to	IEC EN 61010-2-030
Supplied assembly material	MUR/M8x0,5; SP4
Remarks	Accessories: Flat connecting receptacle FSH2,8x0,8; Tube spanner SS4; Tube spanner SS2-S
Approvals	UR