


# SAF-4N-S10

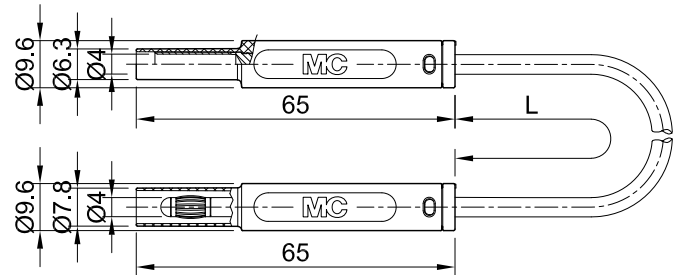

Data sheet SAF-4N-S10 08.2024

Item number 66.1045-\*

Highly flexible. One end with Ø 4 mm MULTILAM plug with rigid insulating sleeve, the other end with Ø 4 mm rigid socket with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT IV, 19 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span> <span style="background-color: blue; color: white; padding: 2px;">23</span> <span style="background-color: yellow; color: black; padding: 2px;">24</span>
Optional color(s)	<span style="background-color: green; color: white; padding: 2px;">25</span> <span style="background-color: grey; color: white; padding: 2px;">29</span>
Lead lengths <input type="text"/>	050; 100; 150; 200 cm
Lead insulation	SIL
Lead cross section	1,0 mm <sup>2</sup>
Test accessory acc. to	IEC EN 61010-031
User-Information	I 145
Approvals	UL, CE