


# SAPK-4N-T05-5KV

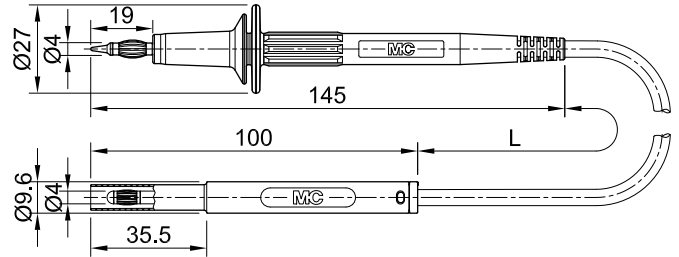

Item number 66.8011-  \*

Highly flexible. One end with Ø 4 mm test probe with spring-loaded MULTILAM, the other end with in-line Ø 4 mm MULTILAM plug with rigid insulating sleeve. Supplied with protective cap.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT IV, 10 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span> <span style="background-color: blue; color: white; padding: 2px;">23</span>
Lead lengths <input type="text"/>	150 cm
Lead insulation	TPE
Lead cross section	0,5 mm <sup>2</sup>
Test accessory acc. to	IEC EN 61010-031
User-Information	I 109
Approvals	CE