
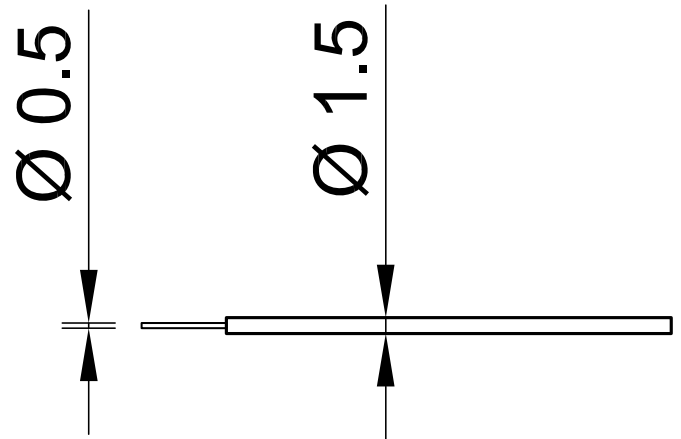


FLEXI-E 0,15

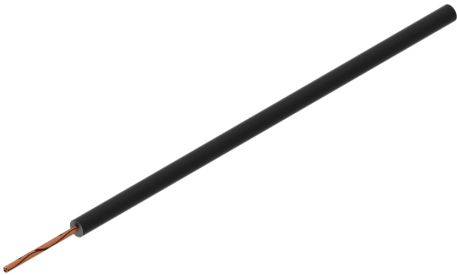

Item number 60.7002-*

Highly flexible basic insulated stranded wire 0,15 mm².

Technical data	
Rated Values	AC 500 V, 4 A
Standard color(s) *	21 22 23 25
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	39 x 0,07
Lead weight	3.5 kg/km
Conductor diameter	0.5 mm
Cable diameter	1.5 mm
Insulation thickness	0.5 mm
Approvals	CE, UKCA, EAC