
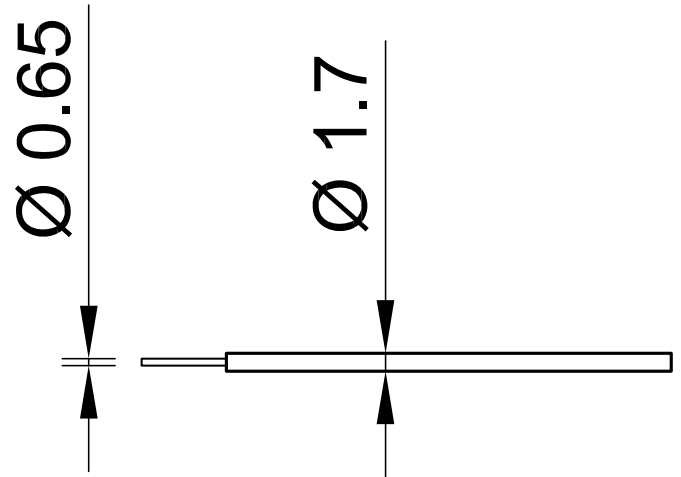


FLEXI-E 0,25

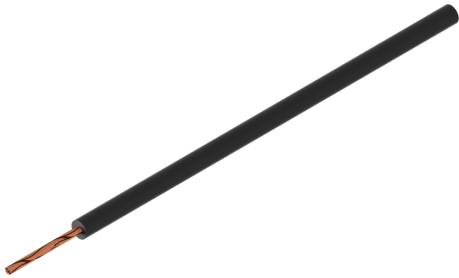

Item number 60.7003-*

Highly flexible basic insulated stranded wire 0.25 mm².

Technical data	
Rated Values	AC 500 V, 6 A
Standard color(s) *	21 22 23 24 25
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	66 x 0,07
Lead weight	4.8 kg/km
Conductor diameter	0.65 mm
Cable diameter	1.7 mm
Insulation thickness	0.5 mm
Approvals	CE, UKCA, EAC