


FLEXI-S 6,0

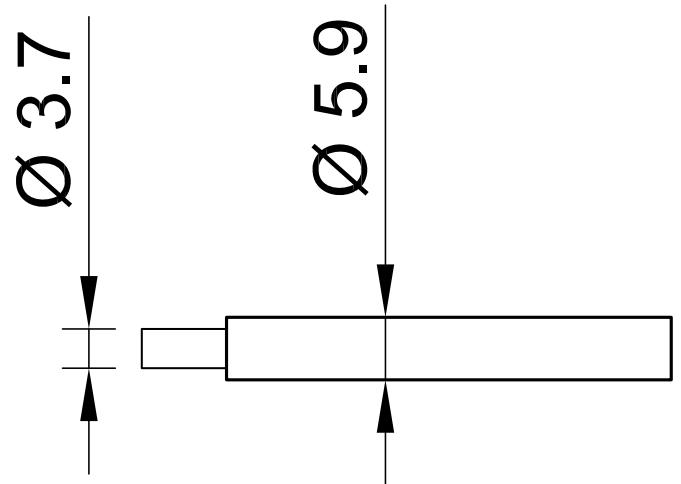

Item number 60.7015-*

Highly flexible stranded wire 6,0 mm² with reinforced insulation.

Technical data	
Rated Values	AC 1000 V, 54 A / DC 1500 V, 54 A
Standard color(s) *	20 21 22 23
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	1548 x 0,07
Lead weight	80.0 kg/km
Conductor diameter	3.7 mm
Cable diameter	5.9 mm
Insulation thickness	1.1 mm
Approvals	UR, CE, UKCA, EAC