


FLEXI-2V/HK 2,5-D

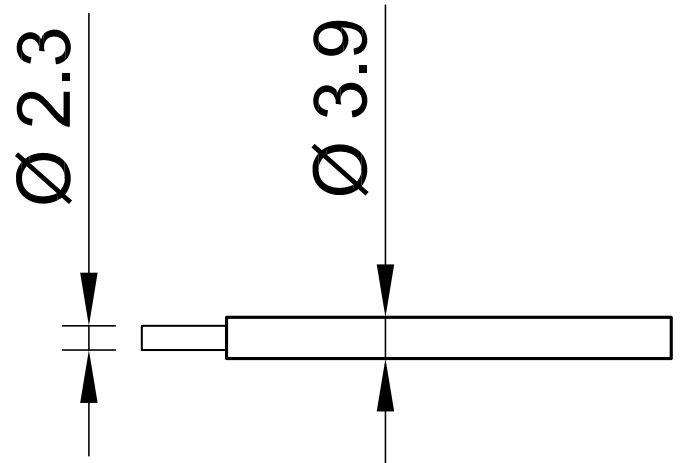

Item number 60.7033-*

Highly flexible stranded wire 2,5 mm² with reinforced, double-layer insulation for the highest safety

Technical data	
Rated Values	AC 1000 V, 32 A / DC 1500 V, 32 A
Standard color(s) *	20 21 22 23 24 25 29
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	651 x 0,07
Lead weight	34.0 kg/km
Conductor diameter	2.3 mm
Cable diameter	3.9 mm
Insulation thickness	0.8 mm
Approvals	UR, CE; UKCA, EAC