


FLEXI-2V 4,0

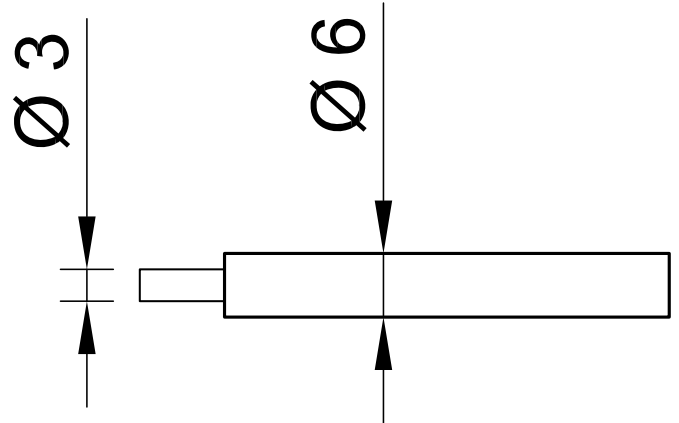

Item number 60.7034-*

Highly flexible stranded wire 4,0 mm² with reinforced, double-layer insulation for the highest safety

Technical data	
Rated Values	AC 1000 V, 42 A / DC 1500 V, 42 A
Standard color(s) *	21 22 23
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	1036x0,07
Lead weight	64.0 kg/km
Conductor diameter	3.0 mm
Cable diameter	6.0 mm
Insulation thickness	1.5 mm
Approvals	UR, CE, UKCA, EAC