


# RG58-PVC

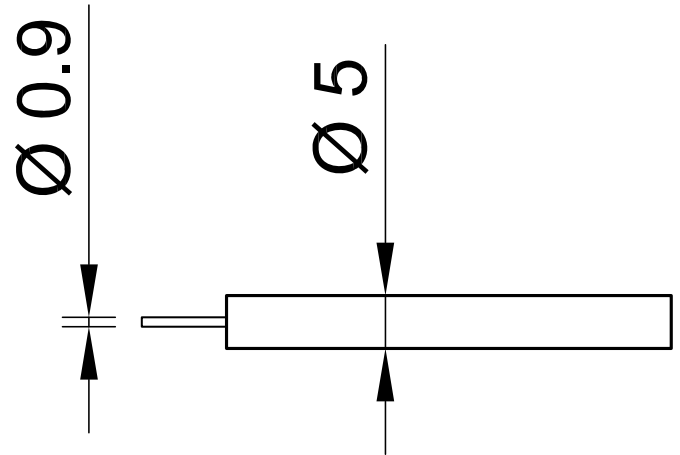

Item number 60.7500-\*

Shielded, highly flexible coaxial cable (tinned).

Technical data	
Rated Values	AC 1000 V / DC 1500 V
Standard color(s) *	<span style="background-color: black; color: white; padding: 2px;">21</span> <span style="background-color: red; color: white; padding: 2px;">22</span> <span style="background-color: blue; color: white; padding: 2px;">23</span>
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Impedance	50.0 Ω
Nominal cross section inner wire	0.5 mm <sup>2</sup>
Lead weight	37.0 kg/km
Cable diameter	5.0 mm
Design inner wire (n x Ø mm)	19 x 0,18
Diameter inner wire	0.9 mm
Design shield (n x Ø mm)	16 x 5 x 0,127
Insulation thickness	0.6 mm
Approvals	UR, CE, UKCA, EAC