


# PLAST-1V 0,50 SN

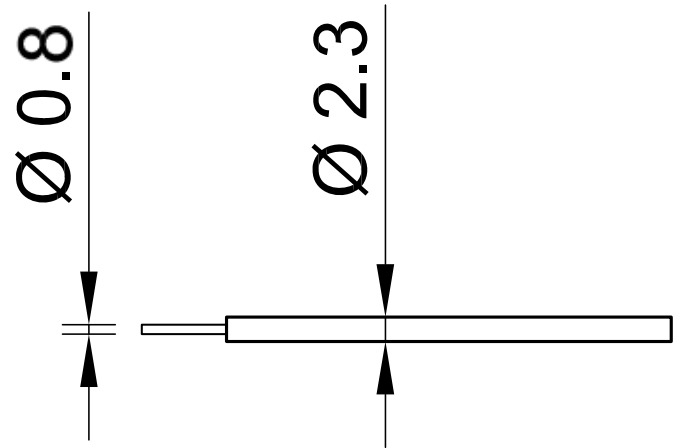

Item number 60.7763-\*

Highly flexible stranded wire 0,50 mm<sup>2</sup> (tinned) with reinforced insulation.

Technical data	
Rated Values	AC 1000 V, 10 A / DC 1500 V, 10 A
Standard color(s) *	21 22
Lead insulation	TPE
Temperature range	-30 °C ... +105 °C
Strand design (n x Ø mm)	129 x 0,07
Lead weight	8.6 kg/km
Conductor diameter	0.8 mm
Cable diameter	2.3 mm
Insulation thickness	0.75 mm
Approvals	UR, CE, UKCA, EAC