
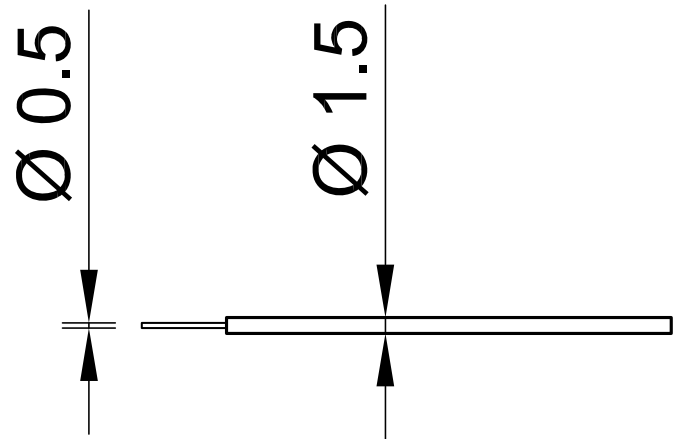


SILI-1V 0,15

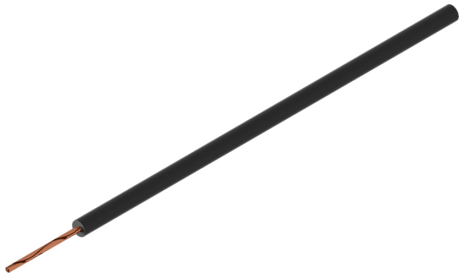

Item number 61.7603-*

Super flexible stranded wire 0,15 mm² with reinforced insulation.

Technical data	
Rated Values	AC 300 V, 6 A
Standard color(s) *	21 22 23 24
Lead insulation	SIL
Temperature range	-50 °C ... +90 °C
Strand design (n x Ø mm)	39 x 0,07
Lead weight	3.2 kg/km
Conductor diameter	0.5 mm
Cable diameter	1.5 mm
Insulation thickness	0.5 mm
Approvals	CE, UKCA, EAC