


SILI-1V 1,0 SN

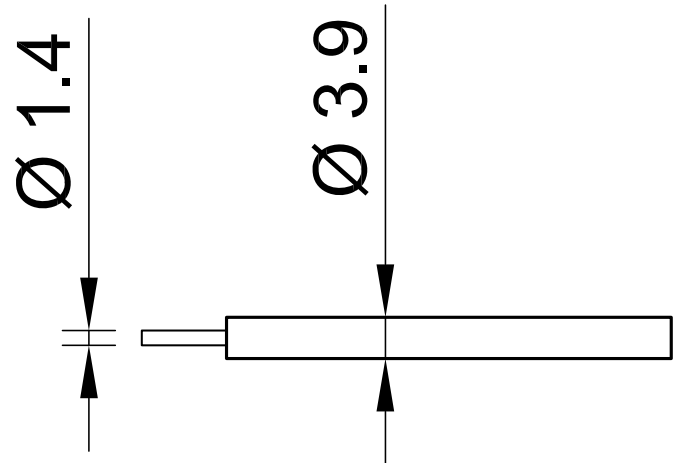

Item number 61.7644-*

Super flexible stranded wire 1,0 mm² (tinned) with reinforced insulation.

Technical data	
Rated Values	AC 1000 V, 19 A / DC 1500 V, 19 A
Standard color(s) *	21 22
Lead insulation	SIL
Temperature range	-50 °C ... +150 °C
Strand design (n x Ø mm)	259 x 0,07
Lead weight	21.0 kg/km
Conductor diameter	1.4 mm
Cable diameter	3.9 mm
Insulation thickness	1.2 mm
Approvals	UR, CE, UKCA, EAC